



A throttling valve that allows pipe routing

Universal Type Throttle Valve AS-DPY00059



Scan the QR code to answer the questionnaire.

- Piping work simplified
- The flow rate can be controlled numerically (With indicator)

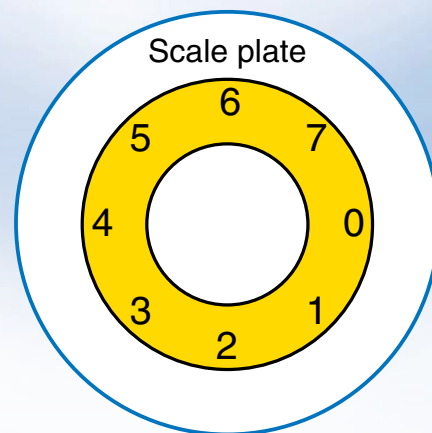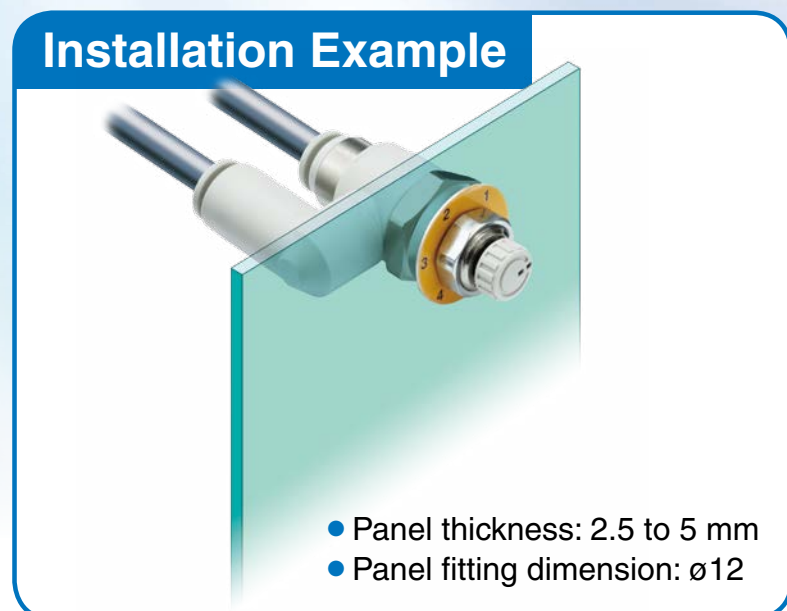

360° Rotation



Basic specifications
Applicable tubing O.D.: $\phi 6$

Caution

The application described here is for reference only and performance is not guaranteed. For actual usage in various other applications, please conduct thorough evaluation and validation testing in order to determine the feasibility under your actual usage conditions. Furthermore, please contact your local SMC sales representative for individual pricing and delivery verification.

No need for a separately installed filter

Built-in Element One-touch Fittings KQ2-X342

- Reduction of filter installation space
- Replaceable element (bronze)



- Prevents contamination from being sent downstream of the fitting



Applicable tubing O.D.	Connection thread	Model	Nominal filtration rating [μm]								
			1	2	5	10	20	40	70	100	120
$\phi 8$	R3/8	Male elbow	●	●	●	●	●	●	●	●	●
		Branch tee	●	●	●	●	●	●	●	●	●
$\phi 10$		Male elbow	●	●	●	●	●	●	●	●	●
		Branch tee	●	●	●	●	●	●	●	●	●
$\phi 3/8"$	NPT3/8	Male elbow	△	△	△	△	△	△	△	●	

△: Available as a special order. For details, please contact SMC.