


Asynchronous type with independently actuating fingers

Low Profile Air Gripper/Asynchronous Type MHF2-X6800




Scan the QR code to answer the questionnaire.

- Fingers 1 and 2 can be actuated independently
- Can be used for various applications

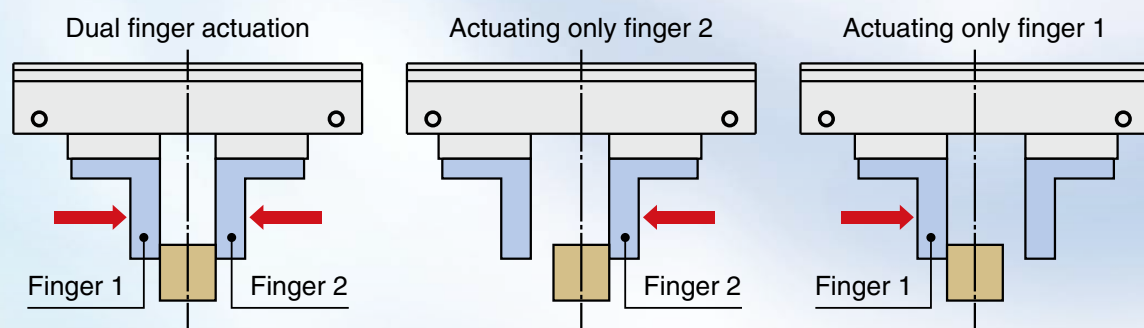


- 2 types of piping connections are available

Axial Piping Type

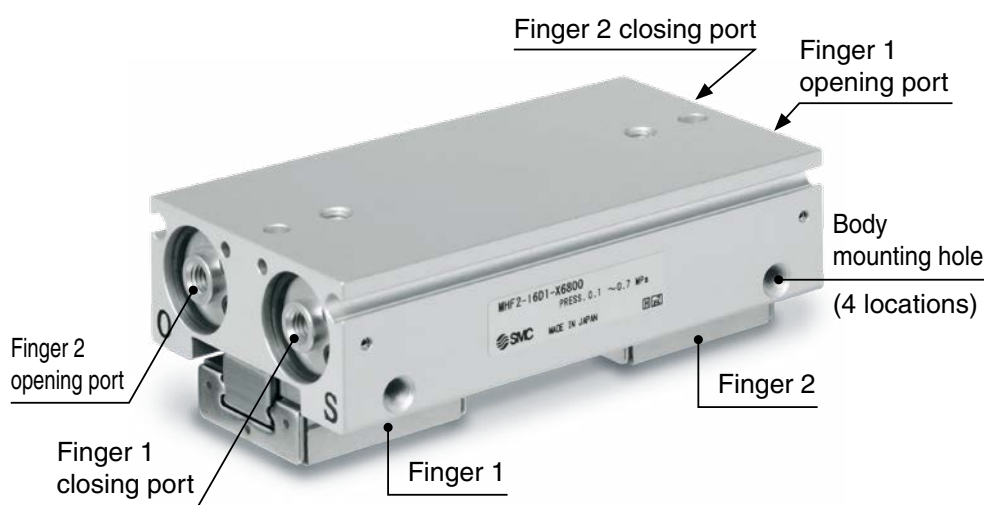


Side Piping Type

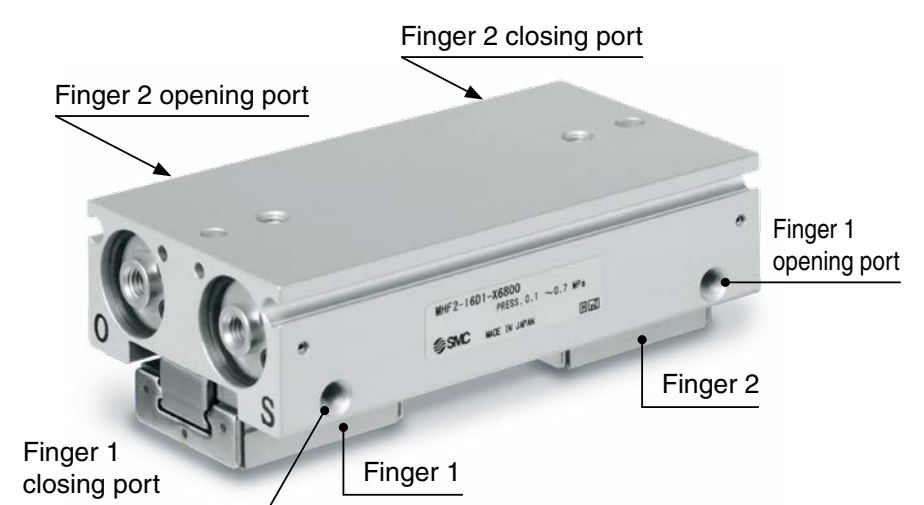

- Can perform gripping with a work reference
- Bore size: $\varnothing 16$
- Gripping force (0.5 MPa): 90 N
- Finger stroke: 32 mm
(One side: 16 mm)

Application Example

Positioning, gripping, and fixing of abrasive material

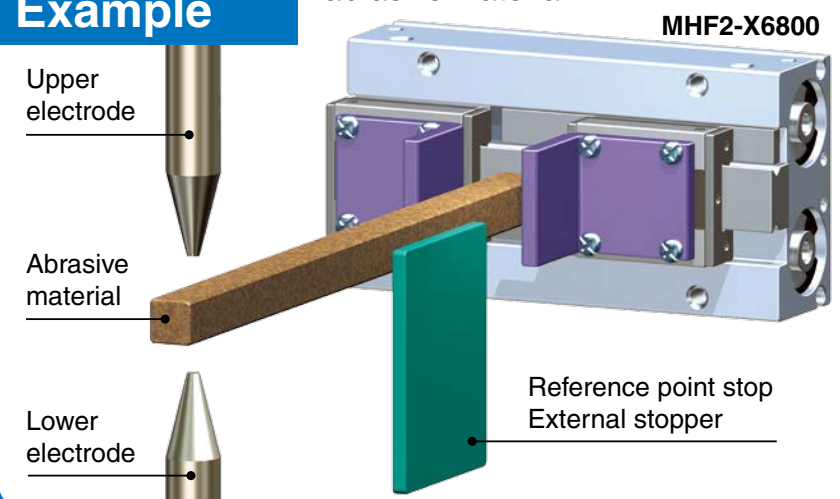

Caution

The application described here is for reference only and performance is not guaranteed. For actual usage in various other applications, please conduct thorough evaluation and validation testing in order to determine the feasibility under your actual usage conditions. Furthermore, please contact your local SMC sales representative for individual pricing and delivery verification.