


# Combined additional metal stopper (for positioning) and shock absorber (for energy absorption)

## Air Slide Table MXQ-X1760



Scan the QR code to answer the questionnaire.

■ The shock absorber can be used with the separate or integrated type

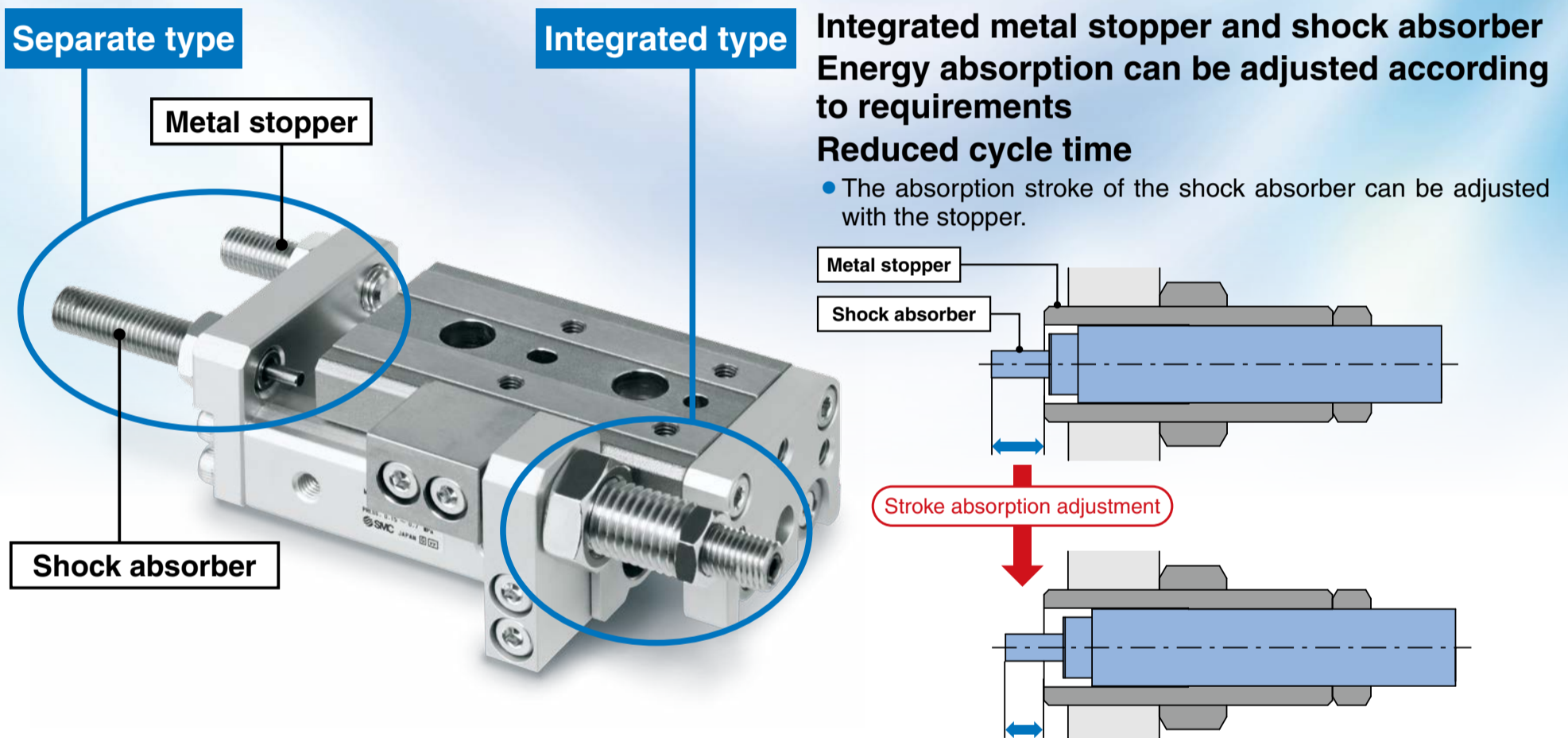

■ Positioning repeatability:  $\pm 0.05$  or less ■ Bore size:  $\varnothing 8, \varnothing 12, \varnothing 16, \varnothing 20, \varnothing 25$


■ Cylinder stroke adjustment range (For  $\varnothing 12$ ):

Extension end	10 mm
Retraction end	17 mm



■ Operating speed range: 50 to 500 mm/s

### Application Examples

For Z motion for pick and place operations

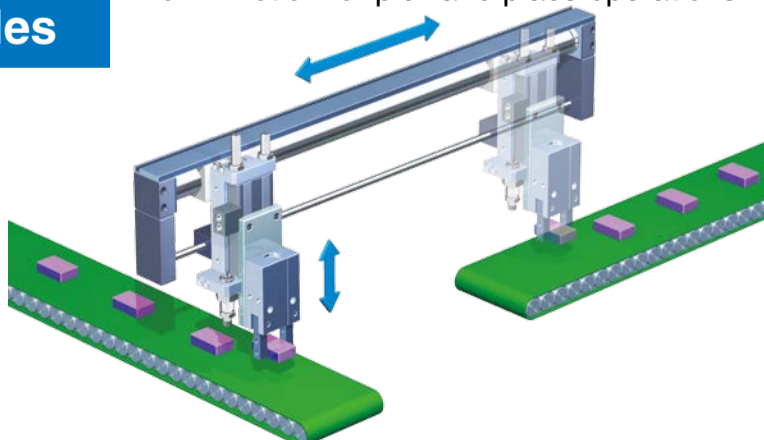

 For positioning of pallets on a conveyor

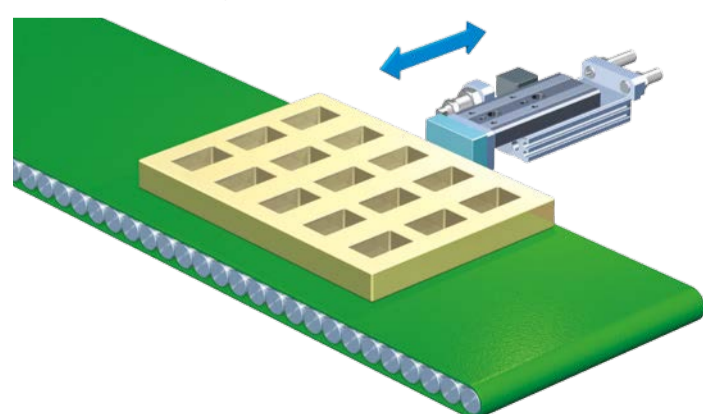

**Caution**

The application described here is for reference only and performance is not guaranteed. For actual usage in various other applications, please conduct thorough evaluation and validation testing in order to determine the feasibility under your actual usage conditions. Furthermore, please contact your local SMC sales representative for individual pricing and delivery verification.