
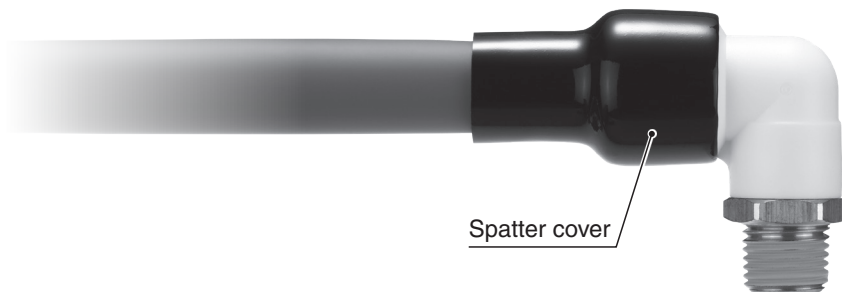


Flame Resistant (Equivalent to UL-94 Standard V-0) Spatter Cover

- Prevents the adhesion and entry of welding spatter
- Uses a flame-retardant material
(Equivalent to UL-94 Standard V-0 Soft PVC)

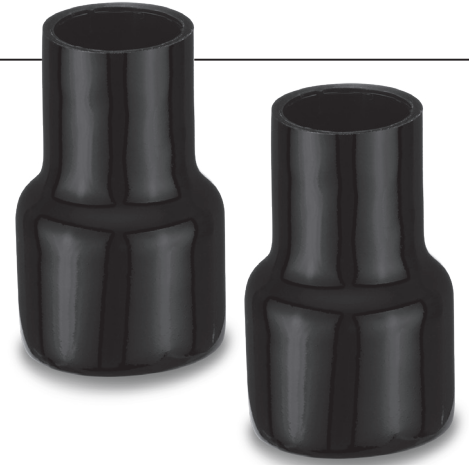

■ Applicable model and size

		FR One-touch Fitting KR Series	Flame Resistant Speed Controller with One-touch Fitting AS-W2 Series	Flame Resistant Flat Head Screwdriver Adjustable Speed Controller AS-W2D Series
				
Applicable fitting Applicable speed controller	Ø 6	KR□06-□□*1	AS□2□1F-□-06W2	AS□2□1F-□-06W2D
	Ø 8	KR□08-□□*1	AS□2□1F-□-08W2	AS□2□1F-□-08W2D
	Ø 10	KR□10-□□*1	AS□2□1F-□-10W2	AS□2□1F-□-10W2D
	Ø 12	KR□12-□□*1	AS□2□1F-□-12W2	AS□2□1F-□-12W2D
Applicable tubing		FR double layer/TRB, TRBU FR three layer/TRTU		
Applicable tubing O.D. (Inner tubing O.D.)		Ø 6, Ø 8, Ø 10, Ø 12		
Ambient temperature		-5 to 60 °C		

*1 This product cannot be used with fittings such as KRU (union "Y") that have tube insertion parts close to each other.
For KRH (male connector) and KRE (bulkhead union) fittings, this product can only protect the release button and resin component parts.

*2 Sales unit: 10 pcs.

KR-□C-X1807



21-EU776-UK

KR-□C-X1807


How to Order

KR-**08**C-X1807

• Applicable tubing O.D.

06	Ø 6
08	Ø 8
10	Ø 10
12	Ø 12

Dimensions

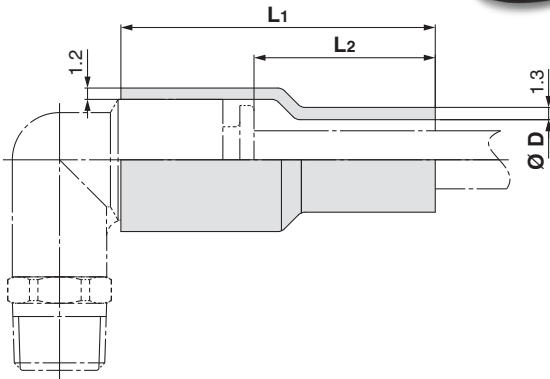

[mm]				
Model	Applicable tubing O.D.	Ø D	L1	L2
KR-06C-X1807	6	8.5	33.3	19.2
KR-08C-X1807	8	10.5	34.5	19.3
KR-10C-X1807	10	12.5	37.2	20.2
KR-12C-X1807	12	14.5	37.9	20.2

SMC Corporation (Europe)

Austria	+43 (0)2262622800	www.smc.at	office@smc.at
Belgium	+32 (0)33551464	www.smc.be	info@smc.be
Bulgaria	+359 (0)2807670	www.smc.bg	office@smc.bg
Croatia	+385 (0)13707288	www.smc.hr	office@smc.hr
Czech Republic	+420 541424611	www.smc.cz	office@smc.cz
Denmark	+45 70252900	www.smc.dk.com	smc@smc.dk.com
Estonia	+372 651 0370	www.smcee.ee	info@smcee.ee
Finland	+358 207513513	www.smc.fi	smc@smc.fi
France	+33 (0)164761000	www.smc-france.fr	supportclient@smc-france.fr
Germany	+49 (0)61034020	www.smc.de	info@smc.de
Greece	+30 210 2717265	www.smchellas.gr	sales@smchellas.gr
Hungary	+36 23513000	www.smc.hu	office@smc.hu
Ireland	+353 (0)14039000	www.smcautomation.ie	sales@smcautomation.ie
Italy	+39 03990691	www.smcitalia.it	mailbox@smcitalia.it
Latvia	+371 67817700	www.smc.lv	info@smc.lv

Lithuania	+370 5 2308118	www.smclt.lt	info@smclt.lt
Netherlands	+31 (0)205318888	www.smc.nl	info@smc.nl
Norway	+47 67129020	www.smc-norge.no	post@smc-norge.no
Poland	+48 222119600	www.smc.pl	office@smc.pl
Portugal	+351 214724500	www.smc.eu	apoiocliente@smc.smces.es
Romania	+40 213205111	www.smcromania.ro	smcromania@smcromania.ro
Russia	+7 (812)3036600	www.smc.eu	sales@smcru.com
Slovakia	+421 (0)413213212	www.smc.sk	office@smc.sk
Slovenia	+386 (0)73885412	www.smc.si	office@smc.si
Spain	+34 945184100	www.smc.eu	post@smc.smces.es
Sweden	+46 (0)86031240	www.smc.nu	smc@smc.nu
Switzerland	+41 (0)523963131	www.smc.ch	info@smc.ch
Turkey	+90 212 489 0 440	www.smcturkey.com.tr	satis@smcturkey.com.tr
UK	+44 (0)845 121 5122	www.smc.uk	sales@smc.uk

South Africa	+27 10 900 1233	www.smcza.co.za	zasales@smcza.co.za
--------------	-----------------	-----------------	---------------------