


FDA (U.S. Food and Drug Administration) and (EU) No 10/2011 Compliant Polyurethane Tubing



In compliance with the FDA's (U.S. Food and Drug Administration) § 177.2600 dissolution test and the (EU) No 10/2011 dissolution test

- Color variations: Black, White, Red, Blue, Yellow, Green, Clear, and Orange
- Size variations (O.D./mm): Ø 4, Ø 6, Ø 8, Ø 10, and Ø 12
- Length per roll: 20 m

Max. Operating Pressure

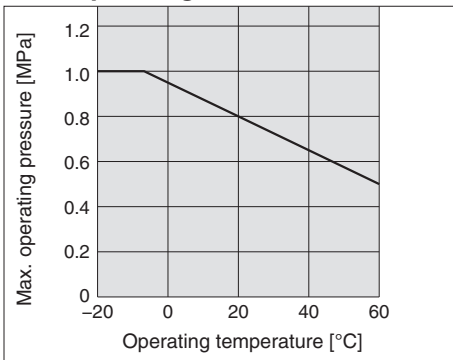

Model

Model	Tubing size (Metric size)				
	TU0425	TU0604	TU0805	TU1065	TU1208
O.D. [mm]	4	6	8	10	12
I.D. [mm]	2.5	4	5	6.5	8
Black (B)	●	●	●	●	●
White (W)	●	●	●	●	●
Red (R)	●	●	●	●	●
Blue (BU)	●	●	●	●	●
Yellow (Y)	●	●	●	●	●
Green (G)	●	●	●	●	●
Clear (C)	●	●	●	●	●
Orange (YR)	●	●	●	●	●

● - 20 m roll

⚠ Precautions


Be sure to read this before handling the products. For safety instructions and fittings & tubing precautions, refer to the "Handling Precautions for SMC Products" and the "Operation Manual" on the SMC website: <https://www.smcworld.com>

Specifications

Fluid	Air, Water				
Max. operating pressure [MPa]	20 °C	0.8			
	40 °C	0.65			
	60 °C	0.5			
Applicable fittings	One-touch fittings, Insert fittings, Miniature fittings				
Min. bending radius [mm]	10	15	20	27	35
Operating temperature	-20 to +60 °C, Water: 0 to 40 °C (No freezing)				
Material	Polyurethane				

⚠ Caution

- Applicable for general industrial water. Please consult with SMC if using any other kind of fluid. Also, the surge pressure must not exceed the maximum operating pressure. If the surge pressure exceeds the maximum operating pressure, it will result in damage to fittings and tubes.
- Abnormal temperature rises caused by adiabatic compression may result in the tube bursting.
- The value of the minimum bending radius is measured at the temperature of 20 °C as shown in the figure below.

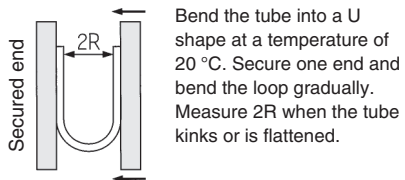

How to Order

TU0425 BU - 20 - X214

Tubing model

Model	O.D. x I.D. [mm]
TU0425	4 x 2.5
TU0604	6 x 4
TU0805	8 x 5
TU1065	10 x 6.5
TU1208	12 x 8


● FDA (U.S. Food and Drug Administration) and (EU) No 10/2011 compliant
● 20 m roll

Color

Symbol	Color	Symbol	Color
B	Black (Opaque)	Y	Yellow (Opaque)
W	White (Opaque)	G	Green (Opaque)
R	Red (Translucent)	C	Clear (Material color)
BU	Blue (Translucent)	YR	Orange (Opaque)

* Note that the model number is not printed on the tube body.

 TU-X214



SMC Corporation (Europe)

Austria	+43 (0)2262622800	www.smc.at	office@smc.at
Belgium	+32 (0)33551464	www.smc.be	info@smc.be
Bulgaria	+359 (0)2807670	www.smc.bg	office@smc.bg
Croatia	+385 (0)13707288	www.smc.hr	office@smc.hr
Czech Republic	+420 541424611	www.smc.cz	office@smc.cz
Denmark	+45 70252900	www.smc.dk	smc@smcdk.com
Estonia	+372 6510370	www.smc.ee	info@smcee.ee
Finland	+358 207513513	www.smc.fi	smcfi@smc.fi
France	+33 (0)164761000	www.smc-france.fr	info@smc-france.fr
Germany	+49 (0)61034020	www.smc.de	info@smc.de
Greece	+30 210 2717265	www.smchellas.gr	sales@smchellas.gr
Hungary	+36 23513000	www.smc.hu	office@smc.hu
Ireland	+353 (0)14039000	www.smcautomation.ie	sales@smcautomation.ie
Italy	+39 03990691	www.smcitalia.it	mailbox@smcitalia.it
Latvia	+371 67817700	www.smc.lv	info@smc.lv

Lithuania	+370 5 2308118	www.smclt.lt	info@smclt.lt
Netherlands	+31 (0)205318888	www.smc.nl	info@smc.nl
Norway	+47 67129020	www.smc-norge.no	post@smc-norge.no
Poland	+48 222119600	www.smc.pl	office@smc.pl
Portugal	+351 214724500	www.smc.eu	apoioclientept@smc.smces.es
Romania	+40 213205111	www.smcromania.ro	smcromania@smcromania.ro
Russia	+7 8123036600	www.smc.eu	sales@smcru.com
Slovakia	+421 (0)413213212	www.smc.sk	office@smc.sk
Slovenia	+386 (0)73885412	www.smc.si	office@smc.si
Spain	+34 945184100	www.smc.eu	post@smc.smces.es
Sweden	+46 (0)86031200	www.smc.nu	smc@smc.nu
Switzerland	+41 (0)523963131	www.smc.ch	helpcenter@smc.ch
Turkey	+90 212 489 0 440	www.smcpnomatik.com.tr	info@smcpnomatik.com.tr
UK	+44 (0)845 121 5122	www.smc.uk	sales@smc.uk